


# GuideLed 10021, 10022, 10023, 10024 CG-S

Exit Sign Panel Luminaires

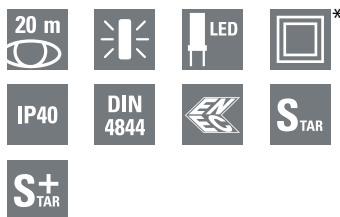


## GuideLed 10021, 10022, 10023, 10024 CG-S

- Exit sign panel luminaire in LED technology for ceiling installation
- Slender design with pictogram width of only 12 mm
- Very good perceptibility due to of high luminance of the white contrasting colour > 500 cd/m<sup>2</sup> in keeping with standard ISO 3864-1 and high uniformity  $L_{min}/L_{max} > 0.8$
- Reduced battery costs due to of especially low power consumption
- Low operating costs due to of low effective power of 2.9W only (1.9W one-sided)
- Minimum service requirement due to high service life of the LEDs (up to 50,000 hours)

GuideLed 10021 CG-S



Dimensions in mm

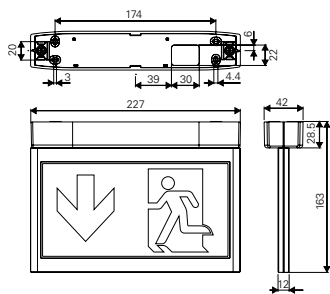


Viewing distance	20 m
Luminous flux $\Phi_E/\Phi_N$ at the end of rated operating time	100 %
Housing material	PC, PMMA
Housing colour	Light grey RAL 7035
Weight	0.39 kg (10021 LED CG-S) 0.49 kg (10022 LED CG-S) 0.54 kg (10023 LED CG-S) 0.70 kg (10024 LED CG-S)
Type of mounting	Ceiling, suspended, recessed installation
Connection terminal	Clamp terminal 2.5 mm <sup>2</sup> reverse-polarity protected
Connection voltage	220 – 240 V AC, 50/60 Hz 176 V – 275 V DC
Current consumption - battery operation (220 V)	one-sided 8 mA – two-sided 12 mA
Power consumption mains operation (apparent power / effective power)	one-sided 4.0 VA / 1.9W two-sided 5.5 VA / 2.9W
Inrush current	1.5 A
Permissible ambient temperature	-20 °C to +40 °C
Light source	LED batten

GuideLed 10022 CG-S



Dimensions in mm

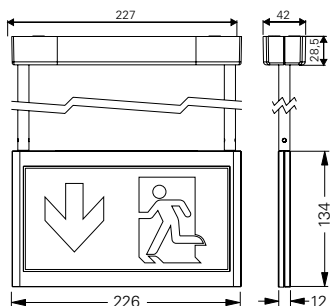

## Ordering details - fastening set

### LED pictograms must ordered separte

	Order No.
Ceiling installation set for GuideLed 10021 CG-S with canopy incl. LED supply and CG-S technology (20 addresses)	40071353610
Ceiling installation set for GuideLed 10022 CG-S with canopy and tube suspension 0.5 m incl. LED supply and CG-S technology (20 addresses)	40071353611
Ceiling installation set for GuideLed 10023 CG-S with canopy and tube suspension 1.5 m incl. LED supply and CG-S technology (20 addresses)	40071353612
Ceiling installation set for GuideLed 10024 CG-S incl. recessed installation housing incl. LED supply and CG-S technology (20 addresses)*	40071353613

## Ordering details - accessories

### Scope of supply


	Order No.
Chain fastening for 10021 CG-S	40071353645
Concrete installation GuideLed 10024 CG-S, 20 m*	40071352892

\* Ceiling mounting set for GuideLed 10024 and concrete installation box corresponding to protection class I

GuideLed 10024 CG-S



Dimensions in mm

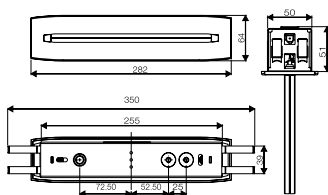

### Ordering details - LED pictograms\*

Scope of supply		Order No.
LED pictogram PL/PR, for GuideLed 10021/10022/10023/10024 CG-S, ISO 7010, 20 m		40071354503
LED pictogram PU/PU, for GuideLed 10021/10022/10023/10024 CG-S, ISO 7010, 20 m		40071354504
LED pictogram PL/BL, for GuideLed 10021/10022/10023/10024 CG-S, ISO 7010, 20 m		40071354505
LED pictogram PR/BL, for GuideLed 10021/10022/10023/10024 CG-S, ISO 7010, 20 m		40071354506
LED pictogram PU/BL, for GuideLed 10021/10022/10023/10024 CG-S, ISO 7010, 20 m		40071354507
LED pictogram PL/PR-R**, for GuideLed 10021/10022/10023/10024 CG-S, ISO 7010, 20 m		40071354508
LED pictogram PL/PR-W**, for GuideLed 10021/10022/10023/10024 CG-S, ISO 7010, 20 m		40071354509

\*\* R = Arrow from mounting wall  
W = Arrow to mounting wall